


PRODUCT LEGEND	
1	1" NIPPLE (INLET)
2	NUT
3	ADAPTER RING
4	NOT USED
5	304 STAINLESS STEEL FLEXIBLE UNBRAIDED HOSE (7/8" NOMINAL DIAMETER) (LENGTHS AVAILABLE 31", 48", 60", & 72")
6	ADAPTER RING
7	NUT
8	REDUCING OUTLET (AVAILABLE 1/2" OR 3/4" FMPT)
9	CENTER BRACKET ASSEMBLY
10	SQUARE BAR (AVAILABLE IN 24" AND 48" LENGTHS)
11	END BRACKET ASSEMBLY
12	SHEET METAL SCREW
13	#8 X 1/2-INCH SELF-TAPPING SCREW
14	VIC MECHANICAL-T OUTLET STYLE 922 FIRELOCK (1" FMPT)
SEE VICTAULIC SUBMITTAL NUMBER 10.85	

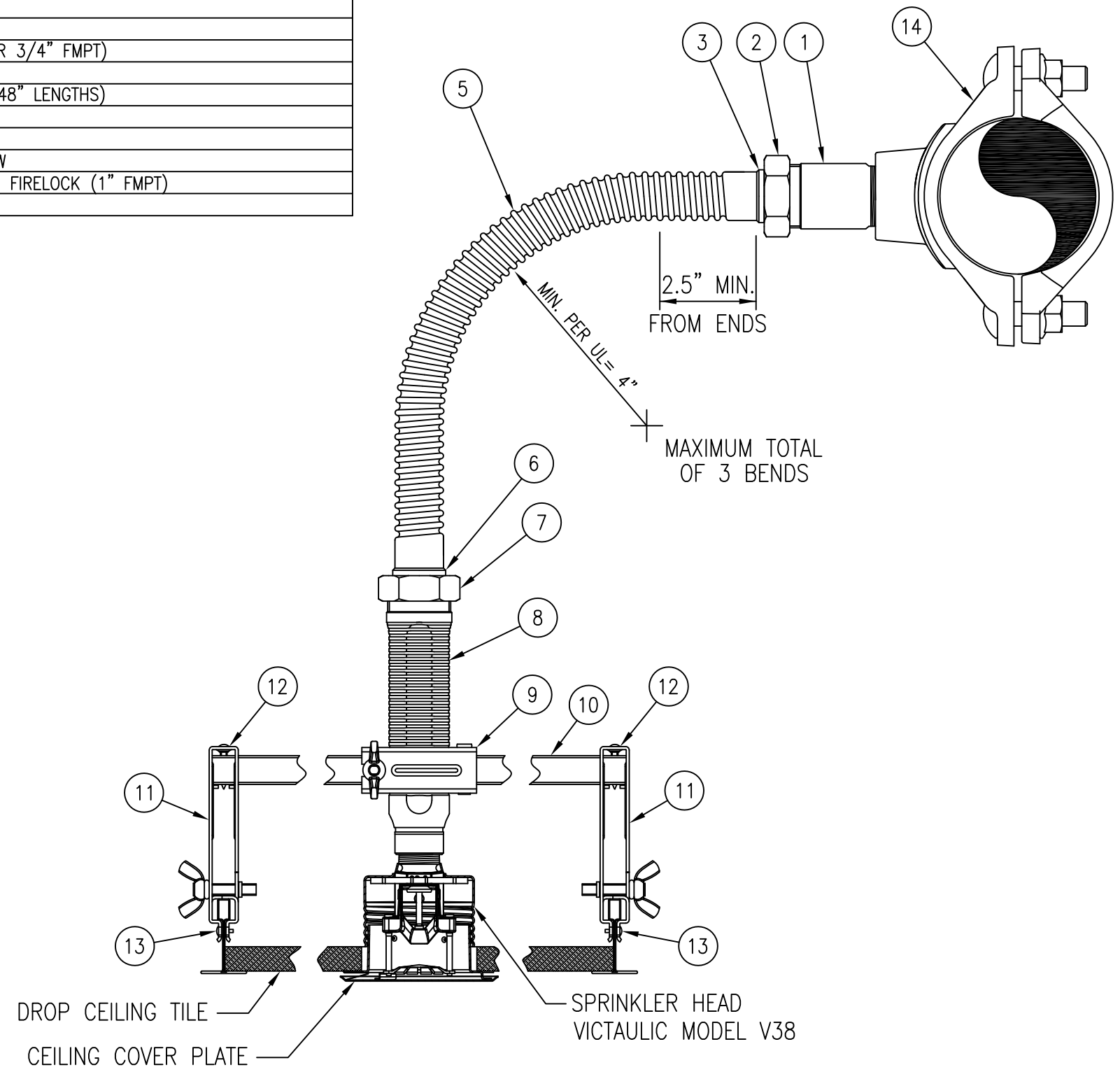

UNBRAIDED AQUAFLEX FLEXIBLE
HOSE SPRINKLER ASSEMBLIES
FOR CONCEALED PENDENT SPRINKLERS



- NOTES:**
- REFER TO VICTAULIC SUBMITTAL 10.85 FOR ADDITIONAL DETAILS.
 - THIS PRODUCT IS LISTED TO APPLICABLE UL STANDARDS AND REQUIREMENTS BY UNDERWRITERS LABORATORIES INC. 2443

Victaulic		CONSTRUCTION PIPING SERVICES DIVISION	
PROJECT: UNBRAIDED AQUAFLEX HOSE ASSEMBLIES		PROJ.# _____	
CUSTOMER: _____		P.O.# _____	
SYSTEM: AQUAFLEX SERIES AQU FOR CONCEALED PENDENT SPRINKLERS			
REF. DWG.: VICTAULIC SUBMITTAL 10.85			#014
DRN.BY: RGS	DATE: 10/29/09	DRAWING NUMBER	REV.
CHK.BY: .	DATE: .	AQUAFLEX-UB-CP	C