


Price List Addendum

EFFECTIVE June 13, 2019


VicFlex™ Brackets

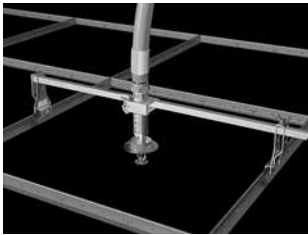


Style AB2 Bracket



Style AB3 Bracket

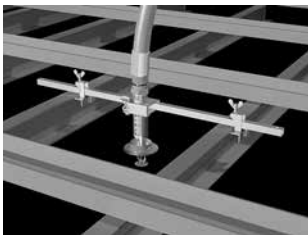

Style AB5 Bracket

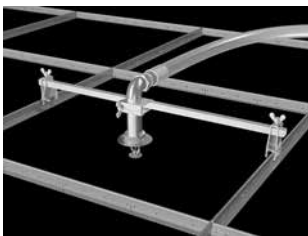

Style AB11 Bracket



Style AB12 Bracket



Style ABBA Bracket

Brackets Description	Size inches	Approx. Wgt. Ea. lb	Victaulic Part No.	Box Quantity	Price Each
Style AB1 For suspended ceilings – allows installation before ceiling tiles in place	24	1.8	A240AB1ADJ	10	\$25.50 ^{NR}
	48	2.6	A480AB1ADJ	10	33.00 ^{NR}
Style AB2 For suspended ceilings – allows installation before ceiling tile is in place; and hard-lid ceilings – allows for vertical sprinkler adjustment	24	1.8	A240AB2000	10	25.50 ^{NR}
	48	2.7	A480AB2000	10	33.00
Style AB3 Surface mount applications, wood, metal and block walls	–	0.3	A000AQFINB	10	11.00 ^{NR}
Style AB4 For hard-lid ceilings with hat furring channel grid systems – allows for vertical sprinkler adjustment	24	1.5	A240AB4000	10	33.00 ^{NR}
	48	2.2	A480AB4000	10	42.50 ^{NR}
Style AB5 For hard-lid ceilings; allows for vertical sprinkler adjustment	24	1.6	A240AB5000	10	25.50 ^{NR}
	48	2.3	A480AB5000	10	33.00 ^{NR}
Style AB7 For suspended ceilings	24	1.4	A000AQFBEE	10	16.50 ^{NR}
	48	1.9	A000AQFB48	10	25.50 ^{NR}
Style AB7 Adjustable For suspended ceilings	24	1.5	A275AQFADJ	10	17.00 ^{NR}
	48	2.0	A551AQFADJ	10	25.00 ^{NR}
Style AB10 For Armstrong® Techzone™ Ceilings	6	1.1	A06AB100TZ	10	33.50 ^{NR}
Style AB11 For lay-in panel suspended t-grid ceilings or drywall suspended t-grid ceilings, allows for low profile installations	24	1.5	A240B11000	10	25.50 ^{NR}
	48	2.7	A480B11000	10	33.00 ^{NR}
Style AB12 For suspended and hard-lid ceilings, allows for vertical sprinkler adjustment, and allows for low profile installation down to 4" 100 mm	–	0.4	A040AQB12	10	11.50
Style ABBA For suspended, exposed and hard-lid ceilings, allows for above mount and cantilever mount.	–	1.3	A000AQB13	10	25.50 ^{NR}
Style ABMM For wood, metal, block walls or ceilings, and hard-lid ceilings, allows surface mount and stand-off mount.	–	0.7	A000AQB11	10	15.00 ^{NR}

NOTE: Items listed in shaded areas are non-cancellable and non-returnable.

^{NR} Non-returnable

VicFlex™ Style AB6 Bracket Assembly Order Form

Order No.	Date
Company Name	
Address	
State/Province	Zip Code/Postal Code
Tag	

Ship To:

Company Name	Zip Code/Postal Code
Address	Email
State/Province	Phone No.
Fax No.	

Bill To:

Quantity (as specified below): If units of different size, type or other option are required, please attach additional form(s) with their specification(s) separately.

VicFlex™ Style AB6 Bracket Assembly

<input type="checkbox"/> A	<input type="checkbox"/> 3	<input type="checkbox"/> 4	<input type="checkbox"/> UB6	<input type="checkbox"/> 4									
Class	Sprinkler Frame	Sprinkler Thread	Deflector Style	Sprinkler Temperature	Sprinkler Response	Sprinkler K-Factor	Sprinkler Finish	Recessed Escutcheon Material³	Sprinkler Barrel Length	Escutcheon Style	Bracket Style	Hose Style	Hose Length
<input type="checkbox"/> A - VicFlex™	<input type="checkbox"/> 33 - V33 Concealed ⁴ <input type="checkbox"/> 36 - V36 STD PEND/ HOR SIDEWALL <input type="checkbox"/> 40 - V40 STD PEND ¹	<input type="checkbox"/> 3 - 1" NPT	<input type="checkbox"/> B - STD PEND <input type="checkbox"/> C - HOR SIDEWALL ² <input type="checkbox"/> P - CONC PENDENT	<input type="checkbox"/> C - 155°F/68°C <input type="checkbox"/> F - 200°F/93°C <input type="checkbox"/> J - 286°F/141°C	<input type="checkbox"/> S - Standard <input type="checkbox"/> Q - Quick	<input type="checkbox"/> 4 - 5.6 <input type="checkbox"/> 5 - 8.0 <input type="checkbox"/> 6 - 11.2	<input type="checkbox"/> 4 - White (RAL 9010) <input type="checkbox"/> N - VC250 ⁴	<input type="checkbox"/> 0 - Cold Rolled Steel <input type="checkbox"/> X - Stainless Steel	<input type="checkbox"/> 120 - 12" <input type="checkbox"/> 180 - 18" <input type="checkbox"/> 240 - 24" <input type="checkbox"/> 300 - 30"	<input type="checkbox"/> 11 - Flush <input type="checkbox"/> 12 - Recessed <input type="checkbox"/> 13 - Sleeve and Skirt <input type="checkbox"/> 15 - Concealed <input type="checkbox"/> 17 - Plain Barrel (Interchangeable Escutcheons)	<input type="checkbox"/> UB6 - AB6	<input type="checkbox"/> 2 - AH2 Hose (NPT) <input type="checkbox"/> 3 - AH2 Hose (BSPT) <input type="checkbox"/> 8 - AH2-CC Hose	<input type="checkbox"/> 4 - 48"

¹ V40 Sprinkler Frame available only as Standard Pendant with K11.2.
² Horizontal Sidewall not available with interchangeable escutcheons.
³ Escutcheon finish will be the same as sprinkler finish.
⁴ UL and FM approved corrosion resistant coating, and V45 and LPCB recognized and approved alternate coating. Appears chrome in color.
⁵ V33 Sprinkler Frame only available with Sprinkler Finish 4 - White (RAL9010) and recessed escutcheon material 0-Cold rolled Steel.

TERMS AND CONDITIONS OF SALE

Victaulic published Terms and Conditions of Sale listed in General Price List will apply. Prices, Designs and Conditions of Sale are subject to change without notice.

P.O. Box 31, Easton, PA 18044-0031 • 4901 Kesslersville Road, Easton, PA 18040 • 1-800-PICK-VIC (1-800-742-5842) • 1-610-250-8817 (fax) • pickvic@victaulic.com

